

Stock Code: **23020LEDDL-BS/WH**

Collection: **Mona**

**PRODUCT INFORMATION**

Base: 23020 Parent: 23020LEDDL  
Mounting Type: Ceiling UPC: 641594220766  
Finish: Brushed Steel  
Diffuser: White

**PRODUCT MEASUREMENTS**

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 16"	Diameter:
Height: 4.5"	Height:
Extension:	
Overall Height:	

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Steel  
Diffuser Material: Glass  
Lamping Type: E-26 (Replaceable LED Jbox: Standard  
Lamping Base: E-26 Lamp Wattage: 10 W  
Lamp Quantity: 3 Total Wattage: 30 W  
Voltage: 120v Lamps Included: Yes

**QUALIFICATIONS**

Location Rating Dry  
Certification: UL (US/Canada) Listed  
ADA Compliant No Energy Star: No  
JA8 Compliant: No Emergency Lighting: No  
Marine Grade: No Warranty: 1 Year

**PHOTOMETRICS**

Dimmable: Yes Nominal Lumens 2400 Lm  
CRI: 90 Delivered Lumens: N/A  
CCT: 3000K  
Recommended Dimmers:  
(TRIAC)Any Standard Dimmer; (ELV)LUTRON Skylark SELV-300P; (MLV)COOPER Aspire 9530SW


Additional Notes:

Project Name: \_\_\_\_\_  
Location: \_\_\_\_\_  
Type: \_\_\_\_\_  
Quantity: \_\_\_\_\_  
Notes: \_\_\_\_\_



LINE DRAWING

IES FILE

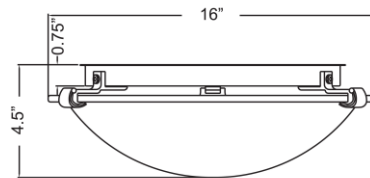

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

