

Stock Code: **23112-ICA**

Collection: Merlot

PRODUCT INFORMATION

Base: 23112 Parent: 23112
Mounting Type: Ceiling UPC: 641594089578
Finish: N/A
Diffuser: Inca

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 5"	Diameter:
Height: 9"	Height:
Extension:	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Glass
Diffuser Material: Glass
Lamping Type: N/A Jbox: N/A
Lamping Base: N/A Lamp Wattage: N/A
Lamp Quantity: N/A Total Wattage: N/A
Voltage: N/A Lamps Included: No

QUALIFICATIONS

Location Rating Dry
Certification: N/A
ADA Compliant: No Energy Star: No
JA8 Compliant: No Emergency Lighting: No
Marine Grade: No Warranty: 1 Year

PHOTOMETRICS


Dimmable: No Nominal Lumens N/A
CRI: N/A Delivered Lumens: N/A
CCT: N/A
Recommended Dimmers:

Additional Notes:

Project Name: _____
Location: _____
Type: _____
Quantity: _____
Notes: _____



LINE DRAWING

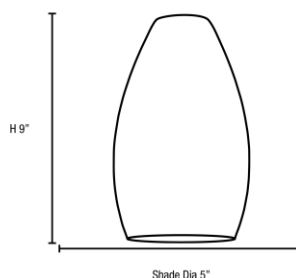

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

The information is subject to change without notice.

11/1/2022

23112-ICA.pdf

