

Stock Code: **23133-BS/CLAM**

Collection: Glass`n Glass

### PRODUCT INFORMATION

Base: 23133 Parent: 23133  
Mounting Type: Ceiling UPC: 641594091793  
Finish: Brushed Steel  
Diffuser: Clear Amber

### PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 4.5"	Diameter:
Height: 10"	Height:
Extension:	
Overall Height:	

### TECHNICAL SPECIFICATIONS

#### SPECIFICATIONS

Frame Material: Glass  
Diffuser Material: Glass  
Lamping Type: N/A Jbox: N/A  
Lamping Base: N/A Lamp Wattage: N/A  
Lamp Quantity: N/A Total Wattage: N/A  
Voltage: N/A Lamps Included: No

#### QUALIFICATIONS

Location Rating Dry  
Certification: N/A  
ADA Compliant No Energy Star: No  
JA8 Compliant: No Emergency Lighting: No  
Marine Grade: No Warranty: 1 Year

#### PHOTOMETRICS

Dimmable: No Nominal Lumens N/A  
CRI: N/A Delivered Lumens: N/A  
CCT: N/A  
Recommended Dimmers:

#### Additional Notes:

Glass retaining spider ring with pins included

Project Name: \_\_\_\_\_

Location: \_\_\_\_\_

Type: \_\_\_\_\_


Quantity: \_\_\_\_\_

Notes:



LINE DRAWING

IES FILE

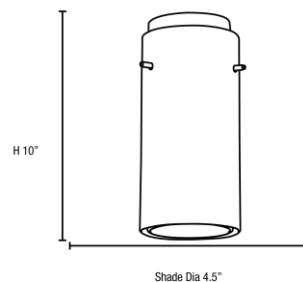

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

Toll Free 800-828-5483 [www.AccessLighting.com](http://www.AccessLighting.com)

14410 Myford Road, Irvine, CA 92606

