

Stock Code: **23892LEDDL-PL-BL**

Collection: Wired

PRODUCT INFORMATION

Base: 23892 Parent: 23892LEDDL-PL
Mounting Type: Ceiling UPC: 641594224191
Finish: Black
Diffuser: N/A

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 23.25"	Diameter: 5.25"
Height: 9"	Height:
Extension:	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Metal
 Diffuser Material: N/A
 Lamping Type: E-26 (Replaceable LED Jbox: Standard
 Lamping Base: E-26 Lamp Wattage: 7 W
 Lamp Quantity: 1 Total Wattage: 7 W
 Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Damp
 Certification: UL (US/Canada) Listed
 ADA Compliant: No Energy Star: No
 JA8 Compliant: No Emergency Lighting: No
 Marine Grade: No Warranty: 1 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 800 Lm
 CRI: 82 Delivered Lumens: 800 Lm
 CCT: 2700K
 Recommended Dimmers:
 (ELV)LUTRON Maestro CL MACL-153M; (TRIAC)LEVITON
 Decora Sureslide 6672; (TRIAC)LEVITON Sureslide 6633-P;
 (TRIAC)LEVITON Trimatron 6684; (TRIAC)LEVITON Decora
 Sureslide 6674


Additional Notes:

Custom Finish 5 Piece Minimum Order Quantity

Project Name: _____
 Location: _____
 Type: _____
 Quantity: _____
 Notes: _____



LINE DRAWING

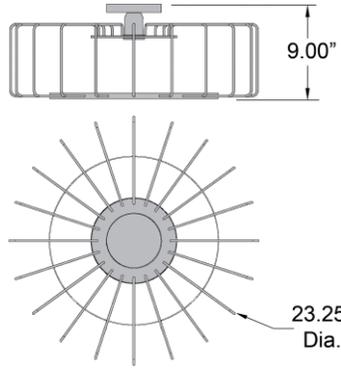

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

