

Stock Code: **31032-BS/ACR**

Collection: Sequoia

### PRODUCT INFORMATION

Base: 31032 Parent: 31032  
Mounting Type: Wall UPC: 641594148923  
Finish: Brushed Steel  
Diffuser: Acrylic Lens

### PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length 25"
Width: 25.25"	Width: 5.25"
Diameter	Diameter:
Height: 5.5"	Height: 0.75"
Extension: 3.75"	
Overall Height:	

### TECHNICAL SPECIFICATIONS

#### SPECIFICATIONS

Frame Material: Metal  
Diffuser Material: Acrylic  
Lamping Type: Bi-Pin (Fluorescent) Jbox: Standard  
Lamping Base: Bi-Pin Lamp Wattage: 24 W  
Lamp Quantity: 2 Total Wattage: 48 W  
Voltage: 120v Lamps Included: Yes

#### QUALIFICATIONS

Location Rating Damp  
Certification: UL (US/Canada) Listed  
ADA Compliant: Yes Energy Star: No  
JA8 Compliant: No Emergency Lighting: No  
Marine Grade: No Warranty: 1 Year

#### PHOTOMETRICS


Dimmable: No Nominal Lumens 3500 Lm  
CRI: N/A Delivered Lumens: N/A  
CCT: 3000K  
Recommended Dimmers:

Additional Notes:  
Horizontal and Vertical Mounting

Project Name: \_\_\_\_\_  
Location: \_\_\_\_\_  
Type: \_\_\_\_\_  
Quantity: \_\_\_\_\_  
Notes:



#### LINE DRAWING

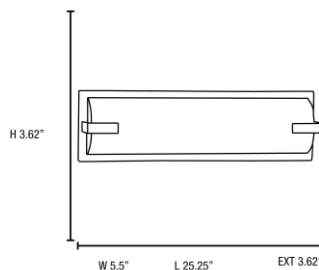

#### IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

Toll Free 800-828-5483 [www.AccessLighting.com](http://www.AccessLighting.com)

14410 Myford Road, Irvine, CA 92606

The information is subject to change without notice. 12/15/2022 31032-BS\_ACR.pdf

