

Stock Code: **50006LEDD-WH/ACR**

Collection: Reel

**PRODUCT INFORMATION**

Base: 50006 Parent: 50006LEDD  
Mounting Type: Ceiling UPC: 641594229394  
Finish: White  
Diffuser: Acrylic Lens

Project Name: \_\_\_\_\_

Location: \_\_\_\_\_

Type: \_\_\_\_\_

Quantity: \_\_\_\_\_

Notes: \_\_\_\_\_

**PRODUCT MEASUREMENTS**

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 6.5"	Diameter:
Height: 4.75"	Height:
Extension:	
Overall Height:	



**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Aluminum  
Diffuser Material: Acrylic  
Lamping Type: SSL (Dedicated LED) Jbox: Standard  
Lamping Base: SSL Lamp Wattage: 20 W  
Lamp Quantity: 1 Total Wattage: 20 W  
Voltage: 120v Lamps Included: Yes


**QUALIFICATIONS**

Location Rating Damp  
Certification: UL (US/Canada) Listed  
ADA Compliant: No Energy Star: No  
JA8 Compliant: No Emergency Lighting: No  
Marine Grade: No Warranty: 5 Year


**PHOTOMETRICS**

Dimmable: Yes Nominal Lumens 1590 Lm  
CRI: 90 Delivered Lumens: 1003 Lm  
CCT: 3000K  
Recommended Dimmers:  
(TRIAC)LEVITON Surslide 6631; (TRIAC)LEVITON Sureslide 6633-P; (TRIAC)LUTRON Skylark S-600 or S-600P

**LINE DRAWING**

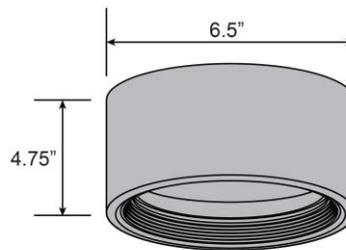

**IES FILE**

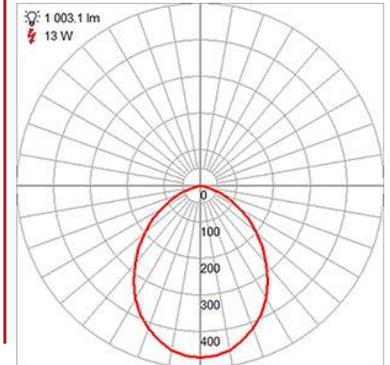

**Additional Notes:**

Optional Color Temperature 100 Piece Minimum Order Quantity;  
Custom Finish 100 Piece Minimum Order Quantity

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

