

Stock Code: **50081-BRZ/OPL**

Collection: Conga

**PRODUCT INFORMATION**

Base: 50081 Parent: 50081  
Mounting Type: Ceiling UPC: 641594080773  
Finish: Bronze  
Diffuser: Opal

**PRODUCT MEASUREMENTS**

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 19"	Diameter:
Height: 5.25"	Height:
Extension:	
Overall Height:	

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Metal  
Diffuser Material: Glass  
Lamping Type: E-26 (Incandescent) Jbox: Standard  
Lamping Base: E-26 Lamp Wattage: 75 W  
Lamp Quantity: 3 Total Wattage: 225 W  
Voltage: 120v Lamps Included: No

**QUALIFICATIONS**

Location Rating: Damp  
Certification: ETL (US/Canada) Listed  
ADA Compliant: No Energy Star: No  
JA8 Compliant: No Emergency Lighting: No  
Marine Grade: No Warranty: 1 Year

**PHOTOMETRICS**


Dimmable: Yes Nominal Lumens: N/A  
CRI: N/A Delivered Lumens: N/A  
CCT: N/A  
Recommended Dimmers:  
(TRIAC)Any Standard Dimmer

Additional Notes:  
Custom Finish 5 Piece Minimum Order Quantity

Project Name: \_\_\_\_\_  
Location: \_\_\_\_\_  
Type: \_\_\_\_\_  
Quantity: \_\_\_\_\_  
Notes: \_\_\_\_\_



**LINE DRAWING**

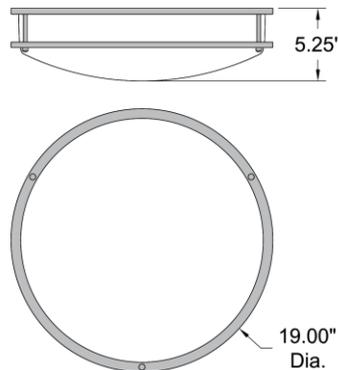

**IES FILE**

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_  
Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

