

Stock Code: **50543LEDDL-CH/CLOP**

Collection: Icicle

PRODUCT INFORMATION

Base: 50543 Parent: 50543LEDDL
Mounting Type: Ceiling UPC: 641594229554
Finish: Chrome
Diffuser: Clear Opal

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 4.25"	Diameter:
Height: 9.5"	Height: 1"
Extension:	
Overall Height: 11-130"	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Metal
 Diffuser Material: Glass
 Lamping Type: G9 (Replaceable LED) Jbox: Standard
 Lamping Base: G9 Lamp Wattage: 4.5 W
 Lamp Quantity: 1 Total Wattage: 4.5 W
 Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Dry
 Certification: UL (US/Canada) Listed
 ADA Compliant: No Energy Star: No
 JA8 Compliant: No Emergency Lighting: No
 Marine Grade: No Warranty: 1 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 450 Lm
 CRI: 83 Delivered Lumens: N/A
 CCT: 2900K
 Recommended Dimmers:
 (TRIAC)LUTRON Diva DVCL-153P; (TRIAC)LUTRON Skylark S-600 or S-600P; (TRIAC)LEVITON illumatech IPI06;
 (TRIAC)LUTRON Skylark CL SCL-153 or SCL-153P

Additional Notes:

10 feet of clear cord included; Custom Finish 200 Piece Minimum Order Quantity

Project Name: _____

Location: _____


Type: _____

Quantity: _____

Notes:



LINE DRAWING

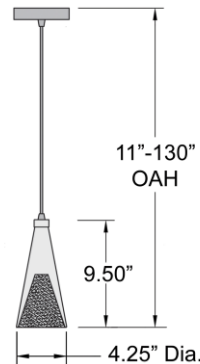

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

