

Stock Code: **52052UJ-BS**

Collection: Apollo

### PRODUCT INFORMATION

Base: 52052 Parent: 52052UJ  
Mounting Type: Ceiling UPC: 641594016567  
Finish: Brushed Steel  
Diffuser: N/A

### PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 3"	Diameter:
Height: 18"	Height:
Extension:	
Overall Height: 20-120"	

### TECHNICAL SPECIFICATIONS

#### SPECIFICATIONS

Frame Material: Metal  
Diffuser Material: N/A  
Lamping Type: GU-5.3 (Halogen) Jbox: Standard  
Lamping Base: GU-5.3 Lamp Wattage: 50 W  
Lamp Quantity: 1 Total Wattage: 50 W  
Voltage: 12v Lamps Included: Yes

#### QUALIFICATIONS

Location Rating Dry  
Certification: UL (US/Canada) Listed  
ADA Compliant: No Energy Star: No  
JA8 Compliant: No Emergency Lighting: No  
Marine Grade: No Warranty: 1 Year

#### PHOTOMETRICS

Dimmable: No Nominal Lumens 514 Lm  
CRI: N/A Delivered Lumens: N/A  
CCT: 2900K  
Recommended Dimmers:

#### Additional Notes:

10 feet of co-axial cable included

Project Name: \_\_\_\_\_

Location: \_\_\_\_\_

Type: \_\_\_\_\_


Quantity: \_\_\_\_\_

Notes: \_\_\_\_\_



LINE DRAWING

IES FILE

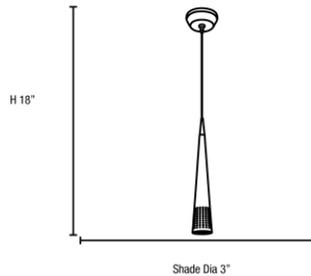

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

Toll Free 800-828-5483 [www.AccessLighting.com](http://www.AccessLighting.com)

14410 Myford Road, Irvine, CA 92606

The information is subject to change without notice. 10/27/2022 52052UJ-BS.pdf

