

Stock Code: **52094LEDDL-BS/CLR**

Collection: Grand

PRODUCT INFORMATION

Base: 52094 Parent: 52094LEDDL
Mounting Type: Ceiling UPC: 641594223484
Finish: Brushed Steel
Diffuser: Clear

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 42"	Diameter: 6.25"
Height: 22"	Height: 1"
Extension:	
Overall Height: 24-66"	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Metal	
Diffuser Material: Glass	
Lamping Type: E-12 (Replaceable LED Jbox: Standard	
Lamping Base: E-12	Lamp Wattage: 4 W
Lamp Quantity: 12	Total Wattage: 48 W
Voltage: 120v	Lamps Included: Yes

QUALIFICATIONS

Location Rating Dry	
Certification: UL (US/Canada) Listed	
ADA Compliant No	Energy Star: No
JA8 Compliant: Yes	Emergency Lighting: No
Marine Grade: No	Warranty: 1 Year

PHOTOMETRICS

Dimmable: Yes	Nominal Lumens 3600 Lm
CRI: 90	Delivered Lumens: N/A
CCT: 2700K	
Recommended Dimmers:	
(ELV)LUTRON Diva DVELV-300P; (TRIAC)LEVITON Trimatron 6684; (ELV)LUTRON Diva DVELV-303P; (ELV)LUTRON Skylark SELV-300P	

Additional Notes:

6, 16, and 22-inch down rods included

Project Name: _____

Location: _____


Type: _____

Quantity: _____

Notes: _____



LINE DRAWING

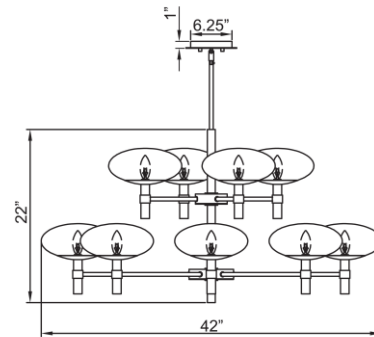

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

