

Stock Code: **52111LEDDL-CH/MIR**

Collection: Glam

**PRODUCT INFORMATION**

Base: 52111 Parent: 52111LEDDL  
Mounting Type: Wall UPC: 641594215939  
Finish: Chrome  
Diffuser: Mirror

**PRODUCT MEASUREMENTS**

<b>FIXTURE</b>	<b>BACKPLATE / CANOPY</b>
Length:	Length 1"
Width: 4.75"	Width: 4.75"
Diameter	Diameter:
Height: 4.75"	Height: 4.75"
Extension: 6.5"	
Overall Height:	

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Metal  
 Diffuser Material: Glass  
 Lamping Type: G9 (Replaceable LED) Jbox: Standard  
 Lamping Base: G9 Lamp Wattage: 4.5 W  
 Lamp Quantity: 1 Total Wattage: 4.5 W  
 Voltage: 120v Lamps Included: Yes

**QUALIFICATIONS**

Location Rating Damp  
 Certification: UL (US/Canada) Listed  
 ADA Compliant No Energy Star: No  
 JA8 Compliant: No Emergency Lighting: No  
 Marine Grade: No Warranty: 1 Year

**PHOTOMETRICS**


Dimmable: Yes Nominal Lumens 450 Lm  
 CRI: N/A Delivered Lumens: N/A  
 CCT: 3000K  
 Recommended Dimmers:  
 (ELV)LUTRON Diva DVELV-300P; (ELV)LUTRON Skylark SELV-300P; (ELV)LUTRON Diva DVELV-303P; (TRIAC)LUTRON Diva DV-600P

Additional Notes:

Project Name: \_\_\_\_\_  
 Location: \_\_\_\_\_  
 Type: \_\_\_\_\_  
 Quantity: \_\_\_\_\_  
 Notes: \_\_\_\_\_



**LINE DRAWING**

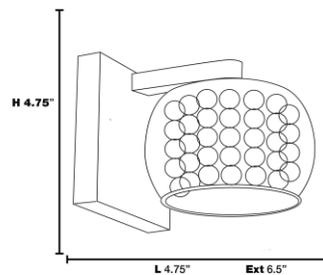

**IES FILE**

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

