

Stock Code: **52220-BRZ**

Collection: **Mirage**

**PRODUCT INFORMATION**

Base: 52220 Parent: 52220  
Mounting Type: Ceiling UPC: 641594016765  
Finish: Bronze  
Diffuser: N/A

**PRODUCT MEASUREMENTS**

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 6"	Diameter: 6"
Height: 5.75"	Height: 1.25"
Extension:	
Overall Height:	

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Metal  
Diffuser Material: N/A  
Lamping Type: GU-10 (Halogen) Jbox: Standard  
Lamping Base: GU-10 Lamp Wattage: 50 W  
Lamp Quantity: 1 Total Wattage: 50 W  
Voltage: 120v Lamps Included: No

**QUALIFICATIONS**

Location Rating Dry  
Certification: ETL (US/Canada) Listed  
ADA Compliant No Energy Star: No  
JA8 Compliant: No Emergency Lighting: No  
Marine Grade: No Warranty: 1 Year

**PHOTOMETRICS**


Dimmable: Yes Nominal Lumens N/A  
CRI: N/A Delivered Lumens: N/A  
CCT: N/A  
Recommended Dimmers:  
(TRIAC)Any Standard Dimmer

Additional Notes:

Project Name: \_\_\_\_\_  
Location: \_\_\_\_\_  
Type: \_\_\_\_\_  
Quantity: \_\_\_\_\_  
Notes:



**LINE DRAWING**

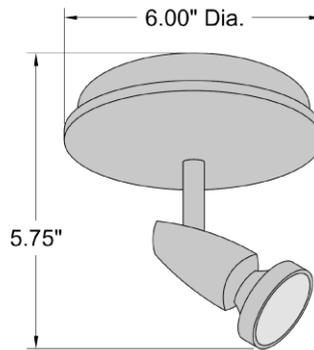

**IES FILE**

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

The information is subject to change without notice. 9/27/2022 52220-BRZ.pdf

