

Stock Code: **62540LEDD-CH/OPL**

Collection: Madison

PRODUCT INFORMATION

Base: 62540 Parent: 62540LEDD
Mounting Type: Wall UPC: 641594234831
Finish: Chrome
Diffuser: Opal

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width: 21.25"	Width:
Diameter	Diameter: 4.5"
Height: 4.5"	Height:
Extension: 3.25"	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Steel
 Diffuser Material: Glass
 Lamping Type: SSL (Dedicated LED) Jbox: Standard
 Lamping Base: SSL Lamp Wattage: 16 W
 Lamp Quantity: 1 Total Wattage: 16 W
 Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Damp
 Certification: ETL (US/Canada) Listed
 ADA Compliant: Yes Energy Star: No
 JA8 Compliant: Yes Emergency Lighting: No
 Marine Grade: No Warranty: 5 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 1280 Lm
 CRI: 90 Delivered Lumens: 1034 Lm
 CCT: 3000K
 Recommended Dimmers:
 (TRIAC)LUTRON Skylark CL SCL-153 or SCL-153P;
 (TRIAC)LUTRON Diva DVCL-153P; (ELV)LEGRAND Touch
 ADTH700RMTUM1; (ELV)LUTRON Maestro CL MACL-153M;
 (ELV)LUTRON Diva DVELV-300P


Additional Notes:

Horizontal and Vertical Mounting; Custom Finish 100 Piece
Minimum Order Quantity; Optional Color Temperature 100 Piece
Minimum Order Quantity


Project Name: _____
 Location: _____
 Type: _____
 Quantity: _____
 Notes: _____



LINE DRAWING

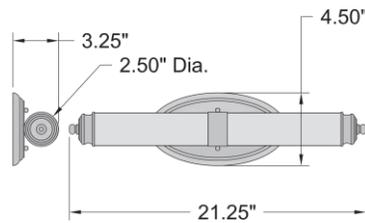

IES FILE

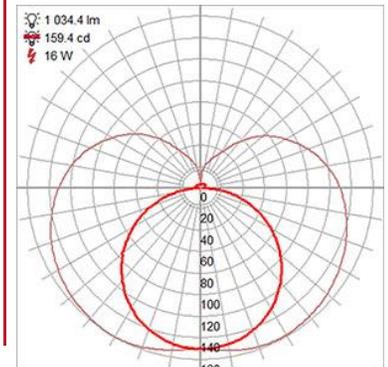

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

