

Stock Code: **62541LEDD-BG/OPL**

Collection: Madison

PRODUCT INFORMATION

Base: 62541 Parent: 62541LEDD
Mounting Type: Wall UPC: 641594234886
Finish: Brushed Gold
Diffuser: Opal

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width: 27.25"	Width:
Diameter	Diameter: 4.5"
Height: 4.5"	Height:
Extension: 3.25"	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Steel	
Diffuser Material: Glass	
Lamping Type: SSL (Dedicated LED)	Jbox: Standard
Lamping Base: SSL	Lamp Wattage: 24 W
Lamp Quantity: 1	Total Wattage: 24 W
Voltage: 120v	Lamps Included: Yes

QUALIFICATIONS

Location Rating: Damp	
Certification: ETL (US/Canada) Listed	
ADA Compliant: Yes	Energy Star: No
JA8 Compliant: Yes	Emergency Lighting: No
Marine Grade: No	Warranty: 5 Year

PHOTOMETRICS

Dimmable: Yes	Nominal Lumens: 1920 Lm
CRI: 90	Delivered Lumens: 1583 Lm
CCT: 3000K	
Recommended Dimmers:	
(ELV)LUTRON Diva DVELV-300P; (TRIAC)LUTRON Skylark CL SCL-153 or SCL-153P; (ELV)LEGRAND Touch ADTH700RMTUM1; (ELV)LUTRON Maestro CL MACL-153M; (TRIAC)LUTRON Diva DVCL-153P	


Additional Notes:

Horizontal and Vertical Mounting; Custom Finish 100 Piece Minimum Order Quantity; Optional Color Temperature 100 Piece Minimum Order Quantity


Project Name: _____
 Location: _____
 Type: _____
 Quantity: _____
 Notes: _____



LINE DRAWING

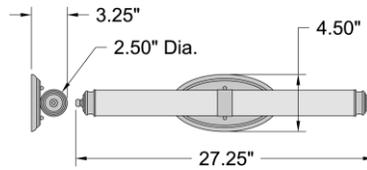

IES FILE

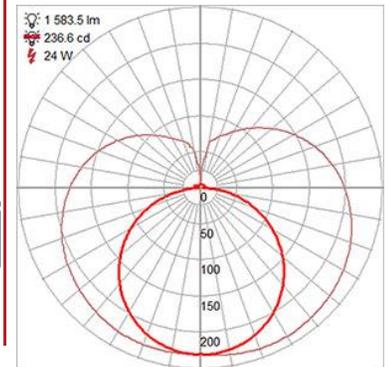

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

