

Stock Code: **63074LEDDL-ML**

Collection: Lincoln

PRODUCT INFORMATION

Base: 63074 Parent: 63074LEDDL
Mounting Type: Ceiling UPC: 641594242140
Finish: Matte Black
Diffuser: N/A

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length: 35"	Length 4.75"
Width: 4.5"	Width:
Diameter	Diameter:
Height: 6.5"	Height: 6"
Extension:	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Metal
Diffuser Material: N/A
Lamping Type: GU-10 (Replaceable LE Jbox: Standard
Lamping Base: GU-10 Lamp Wattage: 5.5 W
Lamp Quantity: 4 Total Wattage: 22 W
Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Dry
Certification: UL (US/Canada) Listed
ADA Compliant: No Energy Star: No
JA8 Compliant: Yes Emergency Lighting: No
Marine Grade: No Warranty: 1 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 2000 Lm
CRI: 90 Delivered Lumens: N/A
CCT: 3000K
Recommended Dimmers:
(TRIAC)LUTRON Diva DVCL-153P; (MLV)COOPER Aspire
9530SW; (ELV)LUTRON Skylark SELV-300P;
(TRIAC)LEGRAND Titan CD703-PW; (ELV)LUTRON Diva
DVELV-300P

Additional Notes:

Custom Finish 100 Piece Minimum Order Quantity


Project Name: _____

Location: _____


Type: _____

Quantity: _____

Notes:

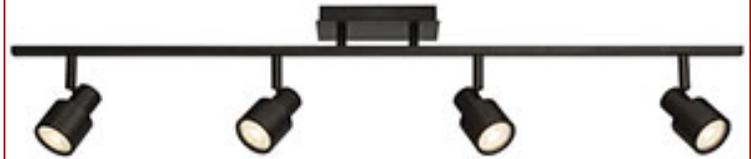

LINE DRAWING

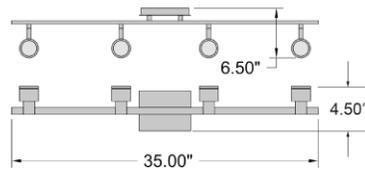

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

The information is subject to change without notice. 11/8/2022 63074LEDDL-ML.pdf

