

Stock Code: **70019LED-CH**

Collection: Unagi

**PRODUCT INFORMATION**

Base: 70019 Parent: 70019LED  
Mounting Type: Wall UPC: 641594191622  
Finish: Chrome  
Diffuser: N/A

**PRODUCT MEASUREMENTS**

<b>FIXTURE</b>	<b>BACKPLATE / CANOPY</b>
Length: 12.75"	Length
Width:	Width:
Diameter 1.75"	Diameter:
Height:	Height:
Extension:	
Overall Height:	

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Metal  
 Diffuser Material: Glass  
 Lamping Type: SSL (Dedicated LED) Jbox: N/A  
 Lamping Base: SSL Lamp Wattage: 3 W  
 Lamp Quantity: 1 Total Wattage: 3 W  
 Voltage: 120v Lamps Included: Yes

**QUALIFICATIONS**

Location Rating Dry  
 Certification: ETL (US/Canada) Listed  
 ADA Compliant: Yes Energy Star: No  
 JA8 Compliant: No Emergency Lighting: No  
 Marine Grade: No Warranty: 5 Year

**PHOTOMETRICS**


Dimmable: No Nominal Lumens 360 Lm  
 CRI: 85 Delivered Lumens: N/A  
 CCT: 3200K  
 Recommended Dimmers:

Additional Notes:  
6 feet of cord included

Project Name: \_\_\_\_\_  
 Location: \_\_\_\_\_  
 Type: \_\_\_\_\_  
 Quantity: \_\_\_\_\_  
 Notes:



**LINE DRAWING**

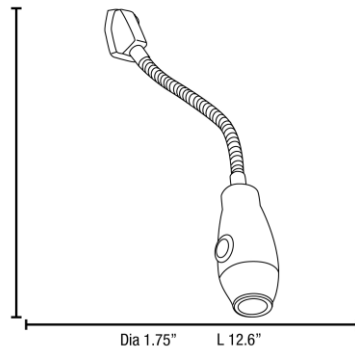

**IES FILE**

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

