

Sleek Shields™

SELF SERVICE FOOD SHIELDS

DOUBLE SIDED - SINGLE TIER

Protected by: Patent No. US 9,010,883 B2



GSGD-40-48 Series Shown

Item #: _____ Qty #: _____
 Model #: _____
 Project #: _____

FEATURES:

- 40" Wide Units
- Front glass locks in place at 15° intervals.
- Attractive, low profile design & easy to clean.
- Stainless steel 1" diameter posts.
- Chamber Lock™ is mounted to post in a fixed position.
- Includes Two 1/4" Heat-Tempered Side Glass.
- 1/4" or 3/8" Heat-Tempered Front Glass Panels (See Chart For "*" Symbol).
- 6 3/4" Standard front glass height.

NSGD Series Stainless Steel Shelving

Shelves have rolled edges on front & rear and square edges on left & right sides.

GSGD Series Glass Top Unit

Features 3/8" Heat-Tempered Glass Top.

CONSTRUCTION:

All TIG welded.
 Exposed stainless steel surfaces polished to a satin finish.

MATERIAL:

1/4" Thick Heat-Tempered Side Glass.
 1/4" or 3/8" Thick Heat-Tempered Front Glass.
 Posts - 1" Stainless Steel
 Chamber Lock™ Sleek Shield Assemblies - Anodized Aluminum.
 Finish - Aluminum components are anodized to a satin finish.
 Stainless components polished.

TOP SHELF:

NSGD Series: Shelf - 18 Ga., Type 430 Stainless Steel.
 GSGD Series: 3/8" Thick Heat-Tempered Top Glass.

Length (L)	w/ STAINLESS STEEL SHELF		w/ GLASS TOP		Approx. Cu. Ft.
	Model #	Approx. Weight	Model #	Approx. Weight	
36"	NSGD-40-36	339 lbs.	GSGD-40-36	368 lbs.	32
48"	NSGD-40-48	391 lbs.	GSGD-40-48	437 lbs.	42
60"	NSGD-40-60*	451 lbs.	GSGD-40-60*	509 lbs.	51
72"	NSGD-40-72*	518 lbs.	GSGD-40-72†	592 lbs.	61
84"	NSGD-40-84†	604 lbs.	GSGD-40-84†	660 lbs.	70
96"	NSGD-40-96†	667 lbs.	GSGD-40-96†	729 lbs.	79
108"	NSGD-40-108*†	725 lbs.	GSGD-40-108*†	798 lbs.	89
120"	NSGD-40-120*†	782 lbs.	GSGD-40-120*†	868 lbs.	98
132"	NSGD-40-132*†	840 lbs.	GSGD-40-132*†	932 lbs.	107
144"	NSGD-40-144††	909 lbs.	GSGD-40-144††	1001 lbs.	117

* 3/8" Thick Heat-Tempered Glass Required For Front Glass
 † Requires a single pair of center legs
 †† Requires two pair of center legs



Advance Tabco's Revolutionary "Chamber Lock" System Makes Rotating Food Shields Easier Than Ever

Optional Accessories

(Compatible With All Advance Tabco Food Shields)



SG-1



SG-C



SG-S

- SG-1** Surface Mounting Brackets for use when access below countertop is not available. Fits 1" Posts. 2" Dia.
- SG-3** Modify Food Shield mounting for countertops exceeding 1 3/4" thickness.
- SG-C** Upgrade Center Food Shield Leg to be cantilevered over installed equipment (Per Leg). Cannot replace End Posts/Brackets. Consult factory for special applications.
- SG-S** Sleek Shield™ horizontal swivel bracket. Used to connect food shields positioned at variable angles.

Custom color for aluminum (**SG-AN**) and stainless steel (**SG-PC**) components available. Consult factory.
 LED lights & mounting of customer-supplied heat lamps is available. Consult factory.

Customer Service Available To Assist You **1-800-645-3166** 8:30 am - 7:00 pm E.S.T.

For Orders & Customer Service:

Email: customer@advancetabco.com or Fax: 631-242-6900

For Smart Fabrication™ Quotes:

Email: smartfab@advancetabco.com or Fax: 631-586-2933


DETAILS and SPECIFICATIONS

TOL ± .500"


ALL DIMENSIONS ARE TYPICAL

NSGD-40 SERIES WITH STAINLESS STEEL SHELF

(NSGD-40-96 Shown with Required Additional Center Post)

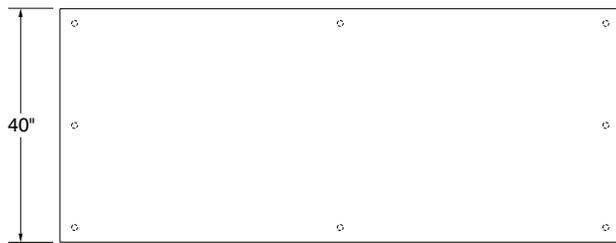

TOP VIEW

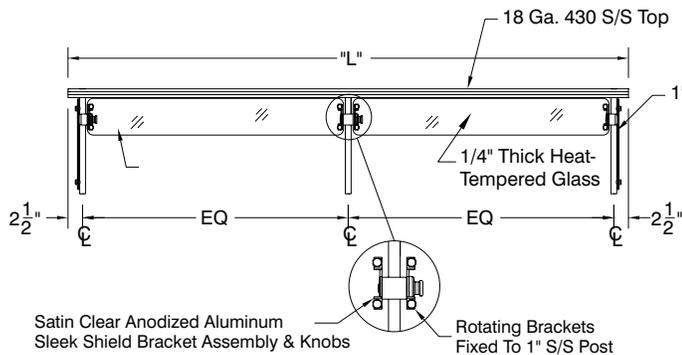


Satin Clear Anodized Aluminum Sleek Shield Bracket Assembly & Knobs


Rotating Brackets Fixed To 1" S/S Post

Standard Concealed Mounting Hardware

Requires access below counter for installation.


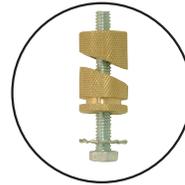


Brass Expander Table Mounting Hardware Included. For traditional undermount installation (1" tubing only)

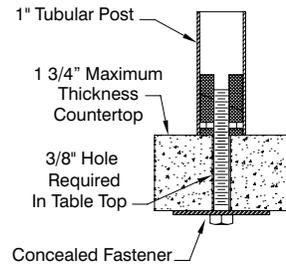


GSGD-40 SERIES WITH GLASS TOP

(GSGD-40-96 Shown with Required Additional Center Post)

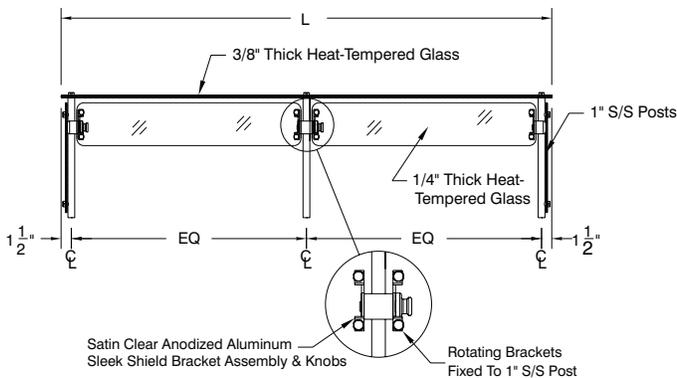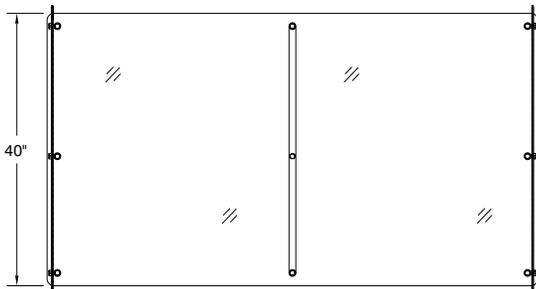

Satin Clear Anodized Aluminum Sleek Shield Bracket Assembly & Knobs

Rotating Brackets Fixed To 1" S/S Post

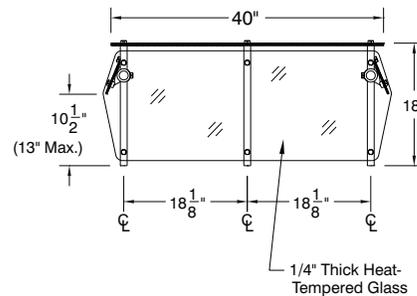

10-1/2" Standard Glass Opening (Maximum 13") From Table To Bottom Of Glass. Max. Load For Top Glass Is 100 Lbs. Even Distributed Wt.

