


Pressure gauge OH-8-GN

Part number: 10089

FESTO

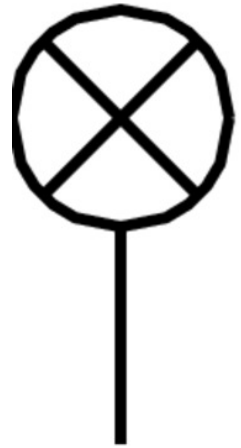

Data sheet

Feature	Value
Type code	OH
Symbol	00991500
Operating pressure	-1 bar ... 8 bar
Explosion prevention and protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Ambient temperature	-10 °C ... 60 °C
Pneumatic connection	Barbed fitting PK-3
Note on materials	RoHS-compliant