


# Axial kit EAMM-A-D19-42A

Part number: 1087642

FESTO

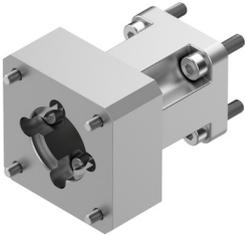

## Data sheet

Feature	Value
Type code	EAMM-A
Mounting position	Any
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transferable torque	1.1 Nm
Product weight	130 g
Interface code, actuator	D19A
Interface code, motor in	42A
Note on materials	Contains paint-wetting impairment substances RoHS-compliant