


# Pressure gauge PAGL-HP3-63-60-G14

Part number: 1166938

FESTO

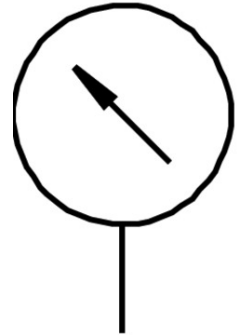

## Data sheet

Feature	Value
Display range	0 bar ... 60 bar
Type code	PAGL
Symbol	00991463
Conforms to standard	EN 837-1
Pressure gauge nominal size	63
Structural design	Bourdon tube pressure gauge
Type of mounting	Line installation
Operating medium	Inert gas Neutral liquids
Operating pressure	0 MPa ... 6 MPa
Operating pressure	0 bar ... 60 bar
Operating pressure	0 psi ... 870 psi
Intermittent load factor	0.66
Measurement accuracy class	1.6
Degree of protection	IP65
Storage temperature	-40 °C ... 70 °C
Temperature of medium	0 °C ... 60 °C
Ambient temperature	0 °C ... 60 °C
Note on materials	RoHS-compliant
Connection position	Centered on rear side
Pneumatic connection	G1/4
Materials in contact with the media	Brass
Material of screwed trunnion	Brass
Housing material	Steel
Inspection window material	PS
Housing colour	Silver
Product weight	80 g
Information on operating and pilot media	No acetylene No oxygen