


Motor flange EAMF-A-28D-40A

Part number: 1199144

FESTO

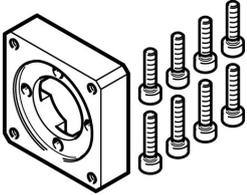

Data sheet

Feature	Value
Type code	EAMF-A
Mounting position	Any
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-10 °C ... 60 °C
Interface code, motor in	40A
Interface code, coupling housing	28D
Note on materials	Contains paint-wetting impairment substances RoHS-compliant