


# Parallel kit EAMM-U-110-D60-100A-120-S1

Part number: 1203112

FESTO

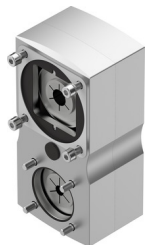

## Data sheet

| Feature                | Value                 |
|------------------------|-----------------------|
| Size                   | 110                   |
| Type code              | EAMM-U                |
| Mounting position      | Any                   |
| Gear ratio             | 1:1                   |
| Max. rotational speed  | 5000 1/min            |
| Storage temperature    | -25 °C ... 60 °C      |
| Relative air humidity  | 0 - 95 %              |
| Degree of protection   | IP65                  |
| Ambient temperature    | -10 °C ... 60 °C      |
| Mass moment of inertia | 799 kgmm <sup>2</sup> |
| No-load driving torque | 0.3 Nm                |
| Transferable torque    | 25 Nm                 |
| Product weight         | 5020 g                |
| Note on materials      | RoHS-compliant        |