


Parallel kit EAMM-U-60-D40-57A-91

Part number: 1210442

FESTO

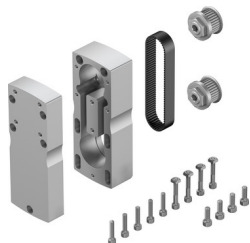

Data sheet

Feature	Value
Size	60
Type code	EAMM-U
Mounting position	Any
Gear ratio	1:1
Max. rotational speed	6000 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	26.7 kgmm ²
No-load driving torque	0.07 Nm
Transferable torque	3 Nm
Product weight	1140 g
Note on materials	RoHS-compliant