


# Manifold rail

## VABM-C8-12E-G14-20-PT-L

Part number: 1247983

FESTO

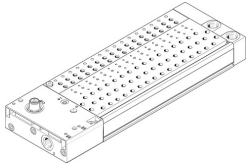

### Data sheet

| Feature                                   | Value                                     |
|-------------------------------------------|-------------------------------------------|
| Width dimension                           | 12 mm                                     |
| Type code                                 | VABM                                      |
| Max. no. of valve positions               | 20                                        |
| Corrosion resistance class (CRC)          | 0 - No corrosion stress                   |
| Max. tightening torque for valve mounting | 0.6 Nm                                    |
| Max. tightening torque for wall mounting  | 5 Nm                                      |
| Product weight                            | 1358 g                                    |
| Pneumatic connection 1                    | G1/4                                      |
| Pneumatic connection 3                    | G1/4                                      |
| Pneumatic connection 5                    | G1/4                                      |
| Note on materials                         | Free of copper and PTFE<br>RoHS-compliant |
| Manifold rail material                    | Wrought aluminum alloy                    |