


Axial kit EAMM-A-D32-55A-S1

FESTO

Part number: 1322180

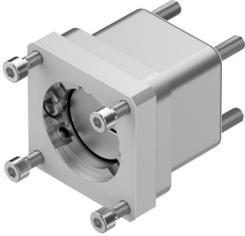

Data sheet

Feature	Value
Type code	EAMM-A
Mounting position	Any
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Transferable torque	6.5 Nm
Product weight	260 g
Interface code, actuator	D32A D32B
Interface code, motor in	55A
Note on materials	Contains paint-wetting impairment substances RoHS-compliant