


# Axial kit EAMM-A-D40-87A-S1

Part number: 1322186

FESTO

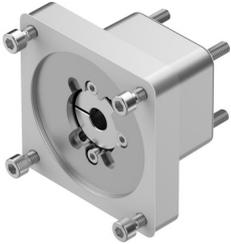

## Data sheet

| Feature                  | Value  |
|--------------------------|--|
| Type code                | EAMM-A   |
| Mounting position        | Any  |
| Storage temperature      | -25 °C ... 60 °C   |
| Relative air humidity    | 0 - 95 %   |
| Degree of protection     | IP65   |
| Ambient temperature      | -10 °C ... 60 °C   |
| Transferable torque      | 12.5 Nm  |
| Product weight           | 530 g  |
| Interface code, actuator | D40A<br>D40B   |
| Interface code, motor in | 87A  |
| Note on materials        | Contains paint-wetting impairment substances<br>RoHS-compliant |