


Clamping module EV-15/63-4

Part number: 13290

FESTO

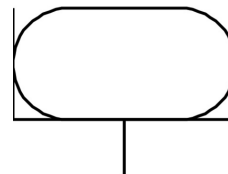

Data sheet

Feature	Value
Stroke	4 mm
Clamping area	15x63
Type code	EV
Mounting position	Any
Mode of operation	Single-acting
Symbol	00991208
Operating pressure	2 bar ... 6 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Ambient temperature	-20 °C ... 40 °C
Product weight	65 g
Type of mounting	With through-hole
Pneumatic connection	M5
Note on materials	Free of copper and PTFE
Housing material	Die-cast aluminum
Diaphragm material	TPE-U(PU)