


# Clamping module EV-20/180-5

Part number: 13293

FESTO

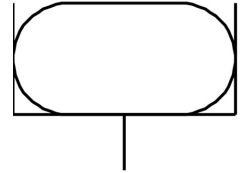

## Data sheet

Feature	Value
Stroke	5 mm
Clamping area	20x180
Type code	EV
Mounting position	Any
Mode of operation	Single-acting
Symbol	00991208
Operating pressure	2 bar ... 6 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Ambient temperature	-20 °C ... 40 °C
Product weight	270 g
Type of mounting	With through-hole
Pneumatic connection	M5
Note on materials	Free of copper and PTFE
Housing material	Die-cast aluminum
Diaphragm material	TPE-U(PU)