


# Braking resistor CACR-KL2-33-W2400

Part number: 1336619

FESTO

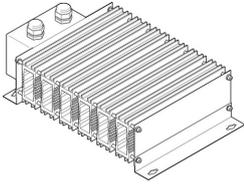

## Data sheet

Feature	Value
Size	600
Type code	CACR
Mounting position	Free convection Vertical
Pulse energy braking resistor at 380 V	21600 Ws
Pulse energy braking resistor at 780 V	21600 Ws
Output at 35% duty cycle and 20°C	3600 W
Braking resistor nominal power	1440 W
Braking resistor nominal power at 380 V	1440 W
Braking resistor nominal power at 780 V	1440 W
Resistance value	33 Ohm
Certification	c CSA us (OL) c UL us - Recognized (OL)
LABS conformity	VDMA24364 zone III
Degree of protection	IP65
Ambient temperature	0 °C ... 50 °C
Product weight	8000 g
Type of mounting	Optionally: With through-hole With accessories
Note on materials	Contains paint-wetting impairment substances RoHS-compliant