


Module connector PAML-MK-90-HP3

Part number: 1367005

FESTO

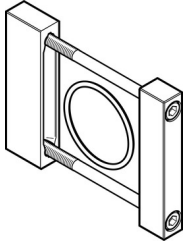

Data sheet

Feature	Value
Size	90
Nominal width DN	36
Type code	PAML
Series	L
Operating pressure	0 MPa ... 5 MPa
Operating pressure	0 bar ... 50 bar
CE marking (see declaration of conformity)	as per EU pressure equipment directive
Operating medium	Compressed air as per ISO 8573-1:2010 [-:--]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Temperature of medium	5 °C ... 60 °C
Ambient temperature	5 °C ... 60 °C
Product weight	150 g
Note on materials	RoHS-compliant
Seals material	NBR
Module connector material	Wrought aluminum alloy
Material of screws	Stainless steel