


Quick coupling
EAMD-67-51-32-32X32-U
Part number: 1379269

FESTO

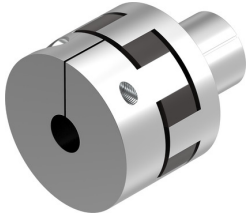

Data sheet

Feature	Value
Diameter of holder 1	32 mm
Diameter of holder 2	32 mm
Size	67
Nominal length	51 mm
Type code	EAMD
Mounting position	Any
Max. rotational speed	4500 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 °C ... 60 °C
Mass moment of inertia	374 kgmm ²
Transferable torque	192 Nm
Product weight	717 g
Note on materials	RoHS-compliant