


Vacuum suction cup VASB-40-1/4-PUR-B

Part number: 1395691

FESTO

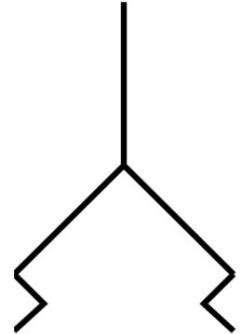

Data sheet

| Feature | Value |
|---|--|
| Suction cup height compensation | 13.7 mm |
| Nominal width | 4 mm |
| Suction cup diameter | 40 mm |
| Suction cup volume | 11.11 cm ³ |
| Effective suction cup diameter | 34.4 mm |
| Type code | VASB |
| Connection position | Top |
| Mounting position | Any |
| Symbol | 00991485 |
| Suction cup shape | Round bellows, 1.5 convolutions |
| Operating pressure | -0.95 bar ... 0 bar |
| Nominal operating pressure | -0.7 bar |
| Operating medium | Atmospheric air based on ISO 8573-1:2010 [7::-:] |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| Ambient temperature | -20 °C ... 60 °C |
| Holding force at nominal operating pressure | 60 N |
| Product weight | 30 g |
| Type of mounting | Via vacuum connection |
| Vacuum connection | G1/4 |
| Color | Blue |
| Shore hardness | 60 +/- 5 |
| Material of screwed trunnion | Die-cast zinc |
| Note on materials | RoHS-compliant |
| Suction cup material | PUR |