


Quick coupling EAMC-67-62-24-24

Part number: 1451407

FESTO

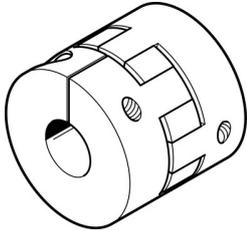

Data sheet

Feature	Value
Diameter of holder 1	24 mm
Diameter of holder 2	24 mm
Size	67
Nominal length	62 mm
Type code	EAMC
Mounting position	Any
Max. rotational speed	4500 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 °C ... 60 °C
Mass moment of inertia	280 kgmm ²
Transferable torque	143 Nm
Product weight	436 g
Note on materials	RoHS-compliant