


# Quick coupling EAMC-30-35-6-10

Part number: 1453062

FESTO

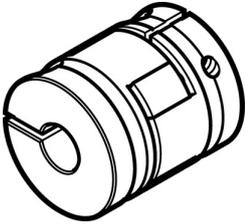

## Data sheet

Feature	Value
Diameter of holder 1	6 mm
Diameter of holder 2	10 mm
Size	30
Nominal length	35 mm
Type code	EAMC
Mounting position	Any
Max. rotational speed	8000 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 °C ... 60 °C
Mass moment of inertia	6.1 kgmm <sup>2</sup>
Transferable torque	7.5 Nm
Product weight	45 g
Note on materials	RoHS-compliant