


One-way flow control valve GRLA-1/8-NPT-B

Part number: 151539

FESTO

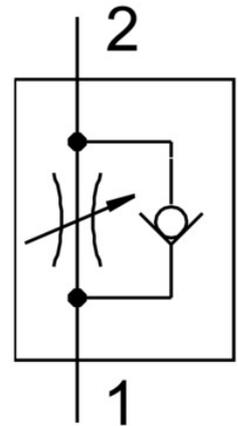

Data sheet

Feature	Value
Type code	GRLA
Valve function	Exhaust air flow control non-return function
Pneumatic connection 1	1/8 NPT
Pneumatic connection 2	1/8 NPT
Adjusting element	Slotted screw
Type of mounting	Screw-in
Ambient temperature	-10 °C ... 60 °C
Symbol	00991452
Operating pressure for entire temperature range	0.3 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Temperature of medium	-10 °C ... 60 °C
Note on materials	RoHS-compliant