


# Vacuum suction cup VAS-125-3/8-NBR

Part number: 152605

FESTO

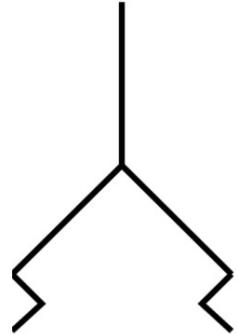

## Data sheet

Feature	Value
Nominal width	7 mm
Suction cup diameter	125 mm
Effective suction cup diameter	105 mm
Type code	VAS
Connection position	Top
Symbol	00991485
Suction cup shape	Round, flat
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Ambient temperature	-20 °C ... 80 °C
Breakaway force at 70% vacuum	606 N
Holding force at nominal operating pressure	606 N
Mounting thread	G3/8
Suction cup mounting	G3/8
Vacuum connection	G3/8
Color	Black
Shore hardness	70 +/- 5
Material of screwed trunnion	Die-cast zinc
Note on materials	RoHS-compliant
Suction cup material	NBR