


Pressure gauge MA-15-10-QS-4

Part number: 153383

FESTO

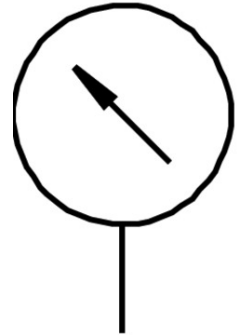

Data sheet

| Feature | Value |
|------------------------------------------|---------------------------------------------------------|
| Display range | 0 bar ... 10 bar |
| Type code | MA |
| Symbol | 00991463 |
| Pressure gauge nominal size | 15 |
| Structural design | Bourdon tube pressure gauge without measuring mechanism |
| Type of mounting | Line installation |
| Operating medium | Inert gas Neutral liquids |
| Operating pressure | 0 MPa ... 1 MPa |
| Operating pressure | 0 bar ... 10 bar |
| Operating pressure | 0 psi ... 145 psi |
| Intermittent load factor | 0.66 |
| Measurement accuracy class | 5 |
| Degree of protection | IP53 |
| Temperature of medium | -20 °C ... 60 °C |
| Ambient temperature | -20 °C ... 60 °C |
| Note on materials | RoHS-compliant |
| Connection position | Centered on rear side |
| Pneumatic connection | QS-4 |
| Materials in contact with the media | Brass |
| Material of screwed trunnion | Brass |
| Housing material | Steel |
| Inspection window material | PC |
| Housing colour | Black |
| Product weight | 10 g |
| Information on operating and pilot media | No acetylene No oxygen |