


Parallel kit
EAMM-U-86-D60-52B/C-102
Part number: 1537000

FESTO

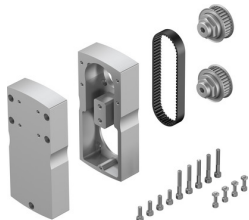

Data sheet

Feature	Value
Size	86
Type code	EAMM-U
Mounting position	Any
Gear ratio	1:1
Max. rotational speed	5000 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	175 kgmm ²
No-load driving torque	0.25 Nm
Transferable torque	9.5 Nm
Product weight	2520 g
Note on materials	RoHS-compliant