


Air line lubricator LOE-1/2-D-MIDI

FESTO

Part number: 159587

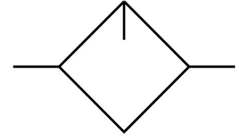

Data sheet

Feature	Value
Size	Midi
Type code	LOE
Series	D
Mounting position	Vertical +/- 5°
Structural design	Proportional standard oil mist lubricator
Max. oil capacity	110 cm ³
Bowl guard	Metal bowl guard
Symbol	00991532
Operating pressure	0 bar ... 16 bar
Minimum flow rate for lubricator function	8 l/min
Standard nominal flow rate	6100 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas
Information on operating and pilot media	Operation with oil lubrication not possible
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:4:-] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	630 g
Type of mounting	With accessories
Pneumatic connection 1	G1/2
Pneumatic connection 2	G1/2
Note on materials	RoHS-compliant
Material of bowl	PC