


Axial kit EAMM-A-D100-140A-S1

Part number: 1600675

FESTO

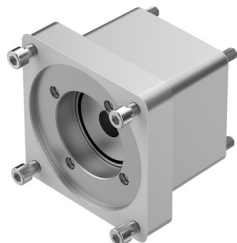

Data sheet

Feature	Value
Type code	EAMM-A
Mounting position	Any
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Transferable torque	143 Nm
Product weight	3460 g
Interface code, actuator	D100B
Interface code, motor in	140A
Note on materials	RoHS-compliant