


Axial kit EAMM-A-P3-28D-28A

Part number: 1703478

FESTO

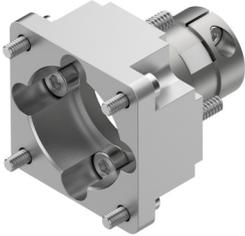

Data sheet

Feature	Value
Type code	EAMM-A
Mounting position	Any
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transferable torque	0.2 Nm
Product weight	30 g
Interface code, actuator	P3-28D
Interface code, motor in	28A
Interface code, coupling housing	28D
Note on materials	RoHS-compliant