


Electric pressure regulator PREL-90-HP3-A4-A-20CFX-S1-4

Part number: 1709136

FESTO

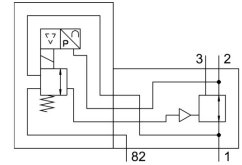

Data sheet

Feature	Value
Size	90
Nominal width DN	24
Type code	PREL
Series	L
Mounting position	Vertical
Actuation type	Electrical
Structural design	Electrically adjustable pressure regulator
Controller function	Outlet pressure constant With primary pressure compensation With secondary exhausting
Symbol	00995417
Operating pressure	0 MPa ... 5 MPa
Operating pressure	0 bar ... 50 bar
Pressure regulation range	0.5 bar ... 20 bar
Nominal operating voltage DC	24 V
Analog output signal range	4 - 20 mA
Analog input signal range	4 - 20 mA
Setpoint/actual values	Current type 4–20 mA
Certification	Special Equipment Type Test Certification
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS conformity	VDMA24364 zone III
Storage temperature	-10 °C ... 60 °C
For use in the food industry	See supplementary material information
Temperature of medium	5 °C ... 50 °C
Ambient temperature	5 °C ... 50 °C
Product weight	6100 g
Electrical connection IN	Plug, M12, 5-pin, A-coded
Electrical connection OUT	Plug, M12, 5-pin, A-coded
Type of mounting	Optionally: On service unit With accessories
Pneumatic connection 1	G1
Pneumatic connection 11	G1/4
Pneumatic connection 2	G1
Pneumatic connection 22	G1/4

Feature	Value
Pneumatic connection 3	G1
Pneumatic connection 82	G3/8
Note on materials	RoHS-compliant
Lower cover material	Aluminum, anodized
Material of spring	Spring steel
Housing material	Aluminum, anodized