


Vacuum suction cup VAS-10-M5-NBR

FESTO

Part number: 173440

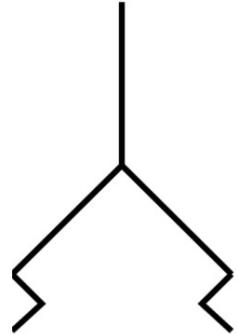

Data sheet

Feature	Value
Nominal width	2 mm
Suction cup diameter	10 mm
Effective suction cup diameter	8 mm
Type code	VAS
Connection position	Top
Symbol	00991485
Suction cup shape	Round, flat
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Ambient temperature	-20 °C ... 80 °C
Breakaway force at 70% vacuum	4.5 N
Holding force at nominal operating pressure	4.5 N
Mounting thread	M5
Suction cup mounting	M5
Vacuum connection	M5
Color	Black
Shore hardness	60 +/- 5
Material of screwed trunnion	Wrought aluminum alloy
Note on materials	RoHS-compliant
Suction cup material	NBR