


Pressure regulator LR-3/8-D-7-O-MIDI-NPT

Part number: 173659

FESTO

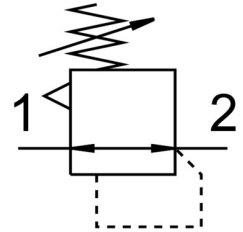

Data sheet

| Feature | Value |
|--|--|
| Size | Midi |
| Type code | LR |
| Series | D |
| Symbol | 00991540 |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| Air quality class at the output | Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas |
| Pneumatic connection 1 | 3/8 NPT |
| Pneumatic connection 2 | 3/8 NPT |
| Note on materials | Free of copper and PTFE RoHS-compliant |