


# Pressure regulator LR-1/2-D-O-MIDI-NPT

Part number: 173661

**FESTO**

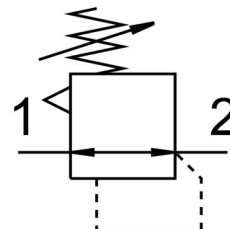

## Data sheet

| Feature                                  | Value                                                              |
|------------------------------------------|--------------------------------------------------------------------|
| Size                                     | Midi                                                               |
| Type code                                | LR                                                                 |
| Series                                   | D                                                                  |
| Symbol                                   | 00991540                                                           |
| Operating medium                         | Compressed air as per ISO 8573-1:2010 [7:4:4]<br>Inert gas         |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC)         | 2 - Moderate corrosion stress                                      |
| Air quality class at the output          | Compressed air as per ISO 8573-1:2010 [7:4:4]<br>Inert gas         |
| Pneumatic connection 1                   | 1/2 NPT                                                            |
| Pneumatic connection 2                   | 1/2 NPT                                                            |
| Note on materials                        | Free of copper and PTFE<br>RoHS-compliant                          |