


Filter regulator LFR-3/4-D-7-MAXI-NPT

Part number: 173810

FESTO

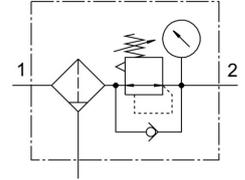

Data sheet

Feature	Value
Size	Maxi
Type code	LFR
Series	D
Mounting position	Vertical
Grade of filtration	40 µm
Condensate drain	Manually rotating
Max. condensate volume	80 ml
Bowl guard	Metal bowl guard
Symbol	00991589
Operating pressure	1 bar ... 16 bar
Max. pressure hysteresis	0.4 bar
Standard nominal flow rate	10000 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [-:9:-] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:8:4] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	1370 g
Type of mounting	Optionally: Line installation With mounting bracket
Pneumatic connection 1	3/4 NPT
Pneumatic connection 2	3/4 NPT
Note on materials	RoHS-compliant
Housing material	Die-cast zinc
Material of bowl	PC