


# Air line lubricator LOE-1/8-D-MINI-NPT

Part number: 173820

FESTO

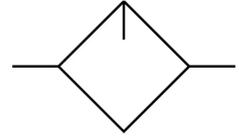

## Data sheet

Feature	Value
Type code	LOE
Max. oil capacity	45 cm <sup>3</sup>
Bowl guard	Metal bowl guard
Symbol	00991532
Operating pressure	16 bar
Minimum flow rate for lubricator function	3 l/min
Standard nominal flow rate	1300 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas
Information on operating and pilot media	Operation with oil lubrication not possible
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:4:-] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	270 g
Type of mounting	With accessories
Pneumatic connection 1	1/8 NPT
Pneumatic connection 2	1/8 NPT
Note on materials	RoHS-compliant
Material of bowl	PC