


Air line lubricator LOE-3/4-D-MIDI-NPT

Part number: 173825

FESTO

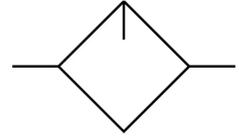

Data sheet

Feature	Value
Type code	LOE
Max. oil capacity	110 cm ³
Bowl guard	Metal bowl guard
Symbol	00991532
Operating pressure	16 bar
Minimum flow rate for lubricator function	8 l/min
Standard nominal flow rate	6300 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas
Information on operating and pilot media	Operation with oil lubrication not possible
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:4:-] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Type of mounting	With accessories
Pneumatic connection 1	3/4 NPT
Pneumatic connection 2	3/4 NPT
Note on materials	RoHS-compliant
Material of bowl	PC