


# Air preparation unit FRC-3/8-D-MINI-NPT

FESTO

Part number: 173844

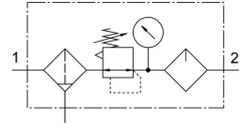

## Data sheet

Feature	Value
Size	Mini
Type code	FRC
Condensate drain	Manual, non-detenting
Grade of filtration	40 µm
Symbol	00991549
Operating pressure	1 bar ... 16 bar
Pressure regulation range	0.5 bar ... 12 bar
Standard nominal flow rate	1200 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [-:9:-] Inert gas
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:8:-] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	660 g
Type of mounting	With accessories
Pneumatic connection 1	3/8 NPT
Pneumatic connection 2	3/8 NPT
Note on materials	RoHS-compliant
Housing material	Die-cast zinc
Material of bowl	PC