


# Air preparation unit FRC-3/4-D-5M-MIDI-A-NPT

Part number: 173873

FESTO

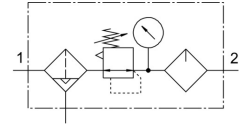

## Data sheet

| Feature                                  | Value  |
|--|--|
| Size                                     | Midi   |
| Type code                                | FRC  |
| Mounting position                        | Vertical   |
| Condensate drain                         | Fully automatic  |
| Grade of filtration                      | 5 µm   |
| Symbol                                   | 00991509   |
| Operating pressure                       | 2 bar ... 12 bar   |
| Pressure regulation range                | 0.5 bar ... 12 bar   |
| Standard nominal flow rate               | 2100 l/min   |
| Operating medium                         | Compressed air as per ISO 8573-1:2010 [7:9:-]<br>Inert gas         |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Air quality class at the output          | Compressed air as per ISO 8573-1:2010 [6:8:-]<br>Inert gas         |
| Temperature of medium                    | -10 °C ... 60 °C   |
| Ambient temperature                      | -10 °C ... 60 °C   |
| Product weight                           | 1440 g   |
| Type of mounting                         | Optionally:<br>Line installation<br>With mounting bracket          |
| Pneumatic connection 1                   | 3/4 NPT  |
| Pneumatic connection 2                   | 3/4 NPT  |
| Note on materials                        | RoHS-compliant   |
| Housing material                         | Die-cast zinc  |
| Material of bowl                         | PC   |